

# CYBEX™ SC800/SC900 SECURE DESKTOP DISPLAYPORT KVM SWITCHES



Superior security and control at the desktop  
NIAP PP 3.0 Compliant, Common Criteria Tested and Certified


## OVERVIEW

### KEY FEATURES

- Advanced isolation between computers and shared peripherals
- Support for DisplayPort in single and dual head models supporting resolutions up to UHD 4K

### BENEFITS

- Compliant with NIAP Protection Profile for Peripheral Sharing Switch, Version 3.0
- Unidirectional Optical Data Diodes assure USB peripheral isolation enabling data flow from devices to host only
- Always-on active anti-tampering system
- Dedicated Peripheral Port (DPP) for connecting authentication devices such as biometric readers and smart card readers
- Hardware-based peripheral isolation loads all firmware on ROM with no keyboard buffering or memory
- Full USB device filtering to assure support for keyboard and mouse only
- Mouse and keyboard switching via secure emulation assures zero delay in switching them between connected sources

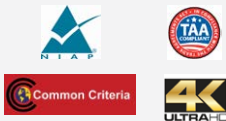

## SPECIFICATIONS

MODEL NUMBER	SC820D/SC920D	SC840D/SC845D/SC940D/SC945D
System Connections	2	4
System Support	DisplayPort 1.2	
Display Connections	Single Head SC8XX, Dual Head SC9XX	
Display Support	HDMI 1.4	
Max Resolution	UHD 4K - 3840 x 2160 @30Hz	

## CONNECTIONS

Console Peripherals	USB Type - A, PS/2	
Computer Peripherals	USB Type - B	
Dedicated Peripheral Port	0	1 (SC845D/SC945D)
Speaker/Headphone Jack	1 x 3.5 mm stereo female	

## MECHANICAL

Enclosure	Steel with plastic front panel	
Dimensions W x D x H in / (mm)	7 x 2.4 x 1.7 (178 x 61 x 43) SC8XXX 7 x 2.4 x 2.2 (178 x 61 x 56) SC9XXX	13.7 x 5 x 1.7 (348 x 127 x 43) SC8XXX 13.7 x 5 x 2.2 (348 x 127 x 56) SC9XXX
Weight lbs / (kg)	1.0 (0.5) SC800 / 1.5 (0.7) SC9XXX	3.0 (1.5) SC800 / 3.7 (1.9) SC9XXX

## POWER

Power Requirements	12V DC 1.5A Power Adapter	35W Max Internal
AC Input Voltage	100 to 240V AC	

## ENVIROMENTAL

Operating Temperature	32° to 104°F; 0° to 40°C	
Storage Temperature	-4° to 140°F; -20° to 60°C	
Humidity	0-80% RH, non-condensing	
Cetifications	CE, RCM, FCC class B, VCCI, TUV US, TUV Canada	
Warranty	3 Years	



SC845D rear panel

## Ordering Details

MODEL NUMBER	CABLE OPTIONS-LENGTH	CABLE DESCRIPTION
SC820D/SC840D	CBL0102 - 6 ft.	1-DISPLAYPORT/1-USB/1-AUDIO
SC845D	CBL0104 - 6 ft.	1-DISPLAYPORT/2-USB/1-AUDIO
SC920D/SC940D	CBL0106 - 6 ft.	2-DISPLAYPORT/1-USB/1-AUDIO
SC945D	CBL0108 - 6 ft.	2-DISPLAYPORT/2-USB/1-AUDIO

VertivCo.com | Vertiv Headquarters, 1050 Dearborn Drive, Columbus, OH, 43085, USA

© 2018 Vertiv Co. All rights reserved. Vertiv and the Vertiv logo are trademarks or registered trademarks of Vertiv Co. All other names and logos referred to are trade names, trademarks or registered trademarks of their respective owners. While every precaution has been taken to ensure accuracy and completeness herein, Vertiv Co. assumes no responsibility, and disclaims all liability, for damages resulting from use of this information or for any errors or omissions. Specifications are subject to change without notice.