


Disclosure and photocopying of this document, exploitation and communication of its contents are not permitted, unless permission is expressly granted. All rights are reserved.

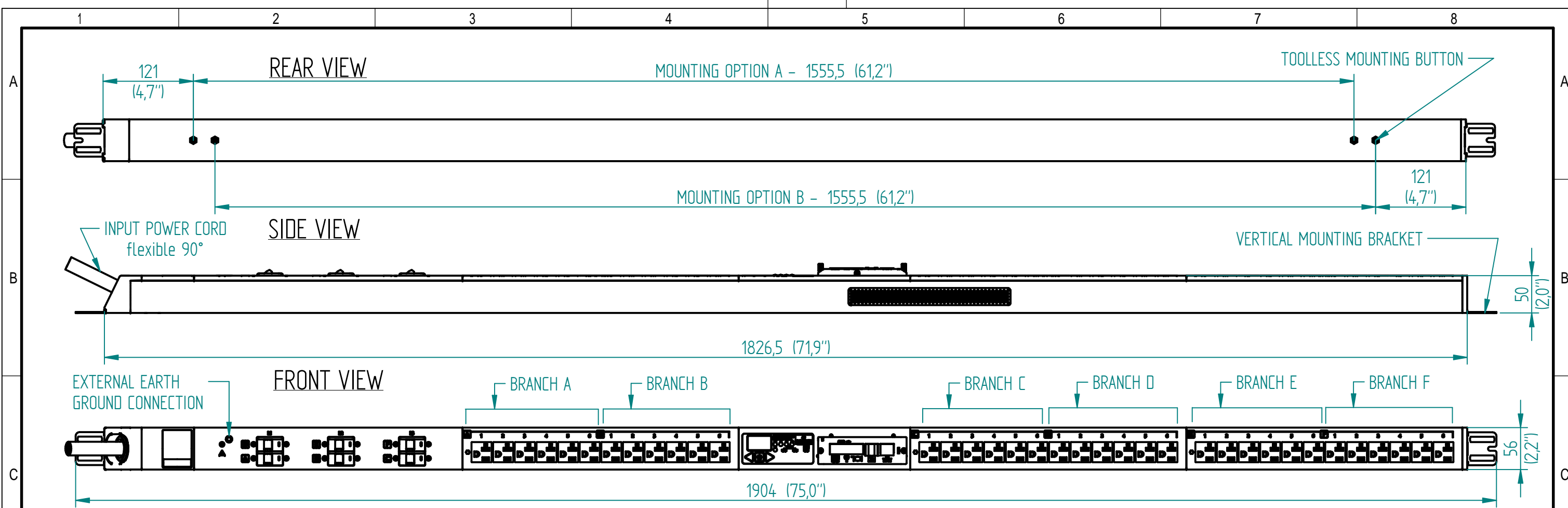

NEMA L21-30P
(30 A, 3/N/PE, 100-120/173-208 V)

NEMA L21-30P

OUTPUT POWER

BRANCH	PHASE	RECEPTACLE TYPE (QUANTITY)	VOLTAGE (V)	MAX. CONTINUOUS AMPS (A)	
				PER RECEPTACLE	PER BRANCH
A	L1	6xNEMA 5-20	100-120	16	16
B	L2	6xNEMA 5-20	100-120	16	16
C	L3	6xNEMA 5-20	100-120	16	16
D	L1	6xNEMA 5-20	100-120	16	16
E	L2	6xNEMA 5-20	100-120	16	16
F	L3	6xNEMA 5-20	100-120	16	16

AGENCY COMPLIANCE:

- UL certification: UL 60950-1 (2nd), CSA C22.2 No. 60950-1-07
- FCC certification
- CB certification: IEC 60950-1 (2nd)

ENVIRONMENTAL RATING:

OPERATING TEMPERATURE: 5 °C - 60 °C (41 °F - 140 °F) NON-CONDENSING, NON-CORROSIVE, 10 % - 90 % RH
 STORAGE TEMPERATURE: -20 °C - 85 °C (-4 °F - 185 °F)
 MAX. OPERATING ALTITUDE: 2000 m

NOTES:

1. UNIT DIMENSIONS: 1826.5 mm (71.9") H x 50 mm (2.0") D x 56 mm (2.2") W
2. UNIT WEIGHT: 4 kg / 8.8 lbs
3. SHIPPING DIMENSIONS: 2017 mm (79.4") H x 297 mm (11.7") D x 176 mm (7.0") W
4. SHIPPING WEIGHT: 6.8 kg / 15 lbs
5. (2) MOUNTING BUTTONS AND (2) MOUNTING BRACKETS SUPPLIED WITH EACH UNIT. EITHER OPTION CAN BE USED TO MOUNT THE PDU.

INPUT POWER

INPUT CORD	INPUT PLUG	WIRE COUNT	FREQUENCY (Hz)	VOLTAGE (V)	RATED AMPS (A)	MAX. CONT. AMPS (A)
10 ft / 3 m	L21 - 30P	3/N/PE	50/60	100-120/173-208	30	24

METERING PARAMETER	MEASUREMENT ACCURACY
VOLTAGE	±1 % + 0.1 VAC
CURRENT	±1.5 % + 0.01 A FROM 1 % TO 10 % OF UNIT RATING; ±1 % FROM >10 % TO 125 % OF UNIT RATING

RoHS COMPLIANT

<p>Dimensions in mm</p>	Allgemeintoleranzen General tolerances		Oberfläche Finish		Werkstoff / Material		Gewicht: Weight: -
	-		-		-		-
Date		Name		Bezeichnung / Description			
15/12/15		Blass		MPH2-NBV_L21-30P_36A			
Checked		Votýpka		Input and Branch Metered			
Approved		-		-			
<p>VERTIV</p>				Zeichnungs-Nr. / Drawing no.		Maßstab Scale	
				MPHB1123		1:5	
Rev. Change Date Name				Verwendet in / Used in		Blatt/Sheet	
C 18131 05.06.2017 Petrú				-		1/1	

Weitergabe sowie Vervielfältigung dieser Unterlage, Verwertung und Mitteilung ihres Inhalts nicht gestattet, soweit nicht ausdrücklich zugestanden. Alle Rechte vorbehalten.