

# Vertiv™ Liebert® GXE UPS 1-3 kVA; 230V IN/OUT

GXE3-1000IMT, GXE3-1500IMT, GXE3-2000IMT, GXE3-3000IMT



## Quick Installation Guide



Thank you for your recent purchase of a Vertiv UPS! We appreciate your business and are confident that your new product will provide many years of uninterruptible power to your connected equipment. With this purchase, you may also want to consider Vertiv's complete line of racks, PDUs, thermal solutions, KVM switches, and serial consoles. If you require any assistance or support, please don't hesitate to reach out to one of our resellers, local representative firms, or refer to Vertiv contacts listed at the end of this document. We stand ready to support you. We sincerely hope that you'll continue to select Vertiv for all of your future infrastructure needs!

The Vertiv Team

**IMPORTANT:** Before installing, connecting to supply, or operating Vertiv™ Liebert® GXE UPS, refer to the SL-55024 Safety and Regulatory Statements Sheet. For detailed installation, operation, maintenance, and troubleshooting information, refer to the Vertiv™ Liebert® GXE User Guide available at [www.Vertiv.com](http://www.Vertiv.com).

**Items Included in the Package**

No.	Items	Quantity
1	Quick installation guide	1
2	Safety and regulatory statements sheet	1
3	Factory test report	1
4	Schuko to IEC60320 C13 input power cable	1
5	British to IEC60320 C13 input power cable	1
6	AUS to IEC60320 C13 input power cable	1
7	IEC60320 C13 to C14 output power cable	See notes
8	USB 2.0 A to B cable	1

**NOTES**

- For items 4, 5, 6 power cables will be C19 for 2-3kVA.
- There are two output power cables in 2-3kVA, 1-1.5kVA has one.

Quick Installation Guide

Mini Tower Installation



GXE3-1000IMT

GXE3-1500IMT / GXE3-2000IMT

GXE3-3000IMT


Starting the UPS



To turn on the UPS, press and hold the *ON/MUTE* button for at least 2 seconds.

Wiring Details	1000VA	1500VA	2000VA	3000VA
Input thermal circuit breaker	10 A	13 A	16 A	20 A
Recommended wire size (all wires)	18 AWG (0.75 mm <sup>2</sup> )	18 AWG (0.75 mm <sup>2</sup> )	14 AWG (2.5 mm <sup>2</sup> )	14 AWG (2.5 mm <sup>2</sup> )
75 °C Copper wire required				

Quick Installation Guide

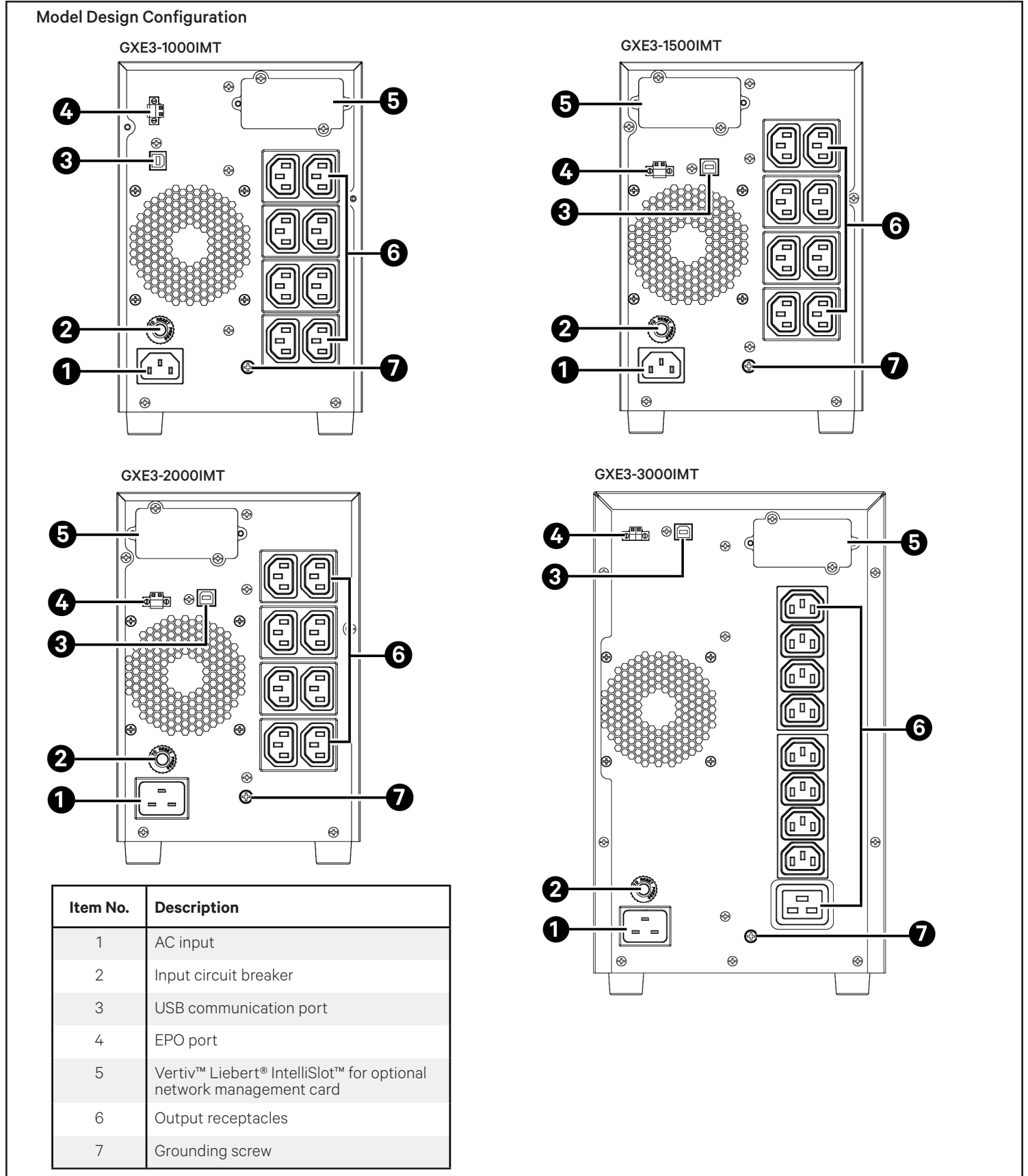

## Vertiv Support Contact Information (Single Phase UPS)

Country	Email	Phone
<b>Europe, Middle-East and Africa</b>		
Belgium	Support for Products Purchased Directly from Vertiv	0080011554499
Czech Republic		
France		
Germany		
Hungary		
Ireland		
Italy		
Luxembourg		
Netherlands		
Poland		
Russia	ServiceWarranty.emea@vertiv.com	81080011554499
South Africa		002780080011554499
Spain		0080011554499
Sweden	Support for Products Purchased from IT Channel	80011554499
Switzerland	warranty.channel.emea@vertiv.com	0080011554499
United Kingdom		
UAE		800035702985
Saudi Arabia		8008446628
Qatar		00800100439
Romania		0800477000
Croatia		0800989019
Nigeria		002347080601125
Ghana		242426263
Turkey		0090 216 444 9545
Egypt		0049872327743
Bahrain		0049872327744
Greece		0080044146622
Denmark		0049872327746
Norway		0049872327747
Finland		0049872327748

Country	Email	Phone
<b>Latin America</b>		
Argentina	Callcenter.Argentina@vertiv.com	0800-1220869
Brazil	sac.crc@vertiv.com	0800-208-8000
Bolivia	Callcenter.Bolivia@vertiv.com	NA
Chile	Callcenter.Chile@vertiv.com	800-395429
Colombia and CCA	Callcenter.Colombia@vertiv.com	018000-125527
Mexico	Callcenter.Mexico@vertiv.com	800-2530414
Paraguay	Callcenter.Paraguay@vertiv.com	NA
Peru	Callcenter.Peru@vertiv.com	0800-77737
Uruguay	Callcenter.Uruguay@vertiv.com	NA
<b>South-East Asia, Australia and New Zealand</b>		
Australia	au.service@vertiv.com	1300-367-686 option 1, and option 1 again
New Zealand	au.service@vertiv.com	0800-100-877
Philippines	ph.service@vertiv.com	+63 2 8620-3655 option 1
Singapore	sg.service@vertiv.com	1800-467-2326
Malaysia	my.service@vertiv.com	1800-28-1388

To contact Vertiv Technical Support: visit [www.Vertiv.com](http://www.Vertiv.com)

© 2023 Vertiv Group Corp. All rights reserved. Vertiv™ and the Vertiv logo are trademarks or registered trademarks of Vertiv Group Corp. All other names and logos referred to are trade names, trademarks or registered trademarks of their respective owners. While every precaution has been taken to ensure accuracy and completeness here, Vertiv Group Corp. assumes no responsibility, and disclaims all liability, for damages resulting from use of this information or for any errors or omissions.

