



Liebert® ITON™

600VA CX



## *Best in class power protection and back up technologies for Offices and Home*


The Liebert® ITON™ 600VA CX is an economical line-interactive UPS that offers full-featured power protection for home or small office computers and electronic equipment. With its unique features and extraordinary performance not normally found in similar products in range.

### Features and Benefits

- Excellent microprocessor control guarantees high reliability
- AVR boost and buck for voltage stabilisation
- Auto restart while AC is recovering
- Simulated sine wave
- Auto charging at Off-mode
- Cold start function
- Generator compatible



Liebert® ITON™ 600VA CX

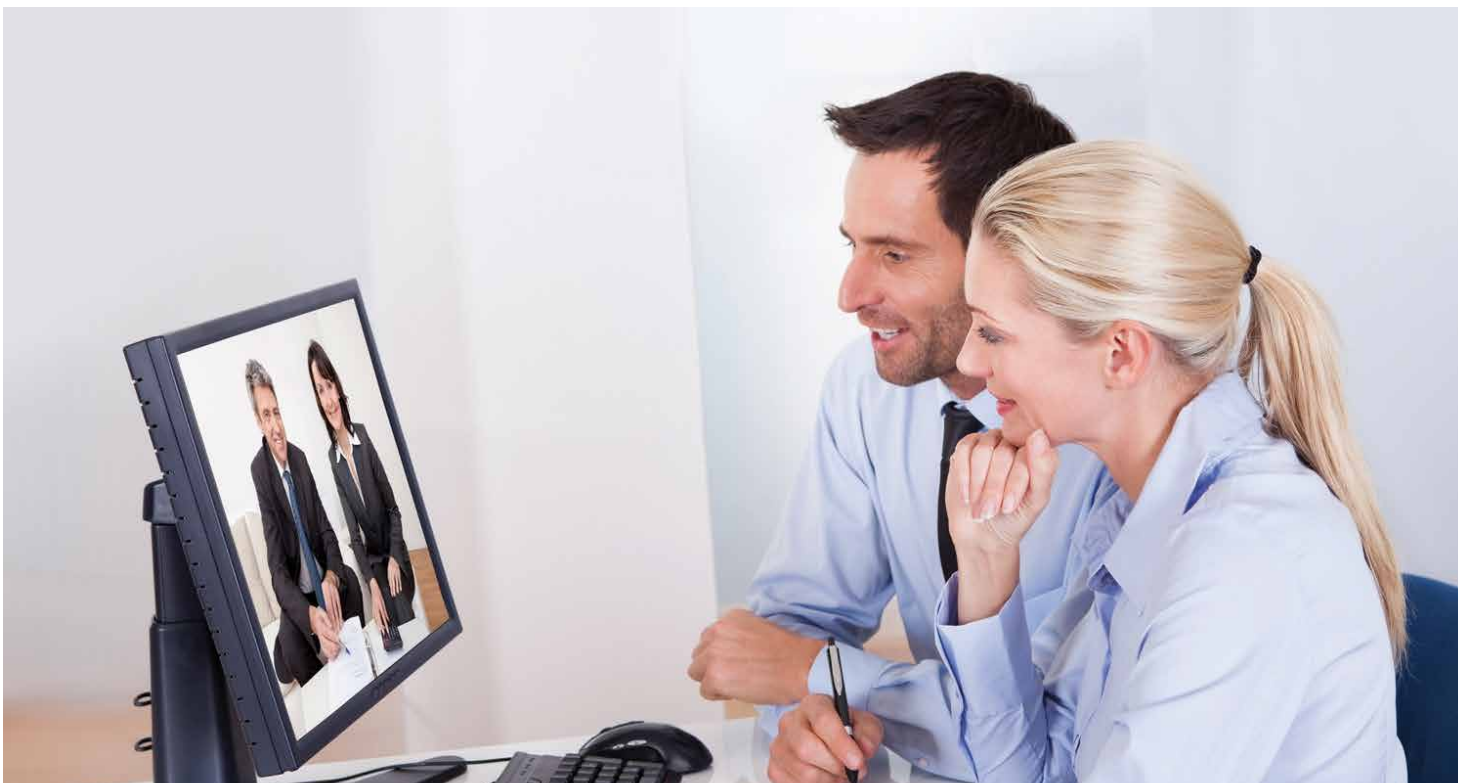

## Technical Specifications

Model	Specification	600VA CX
<b>Capacity</b>	VA/W	600 VA/360 Watt.
<b>Input</b>	Voltage	220/230 VAC
	Voltage Range	140-300 VAC
	Frequency Range	50 Hz
<b>Output</b>	AC Voltage Regulation (Batt. Mode)	±1%
	AC voltage regulation (AC mode)	±10%
	Frequency Range (Batt. Mode)	50 Hz ±1 Hz
	Transfer Time	Typical 2-6 ms
	Waveform (Batt. Mode)	Simulated Sine Wave
	Overload	110% +/-10% Shutdown after 5 mins
<b>Battery</b>	Battery Type & Number	12 V/7 Ah x 1
	Typical Recharge Time	6-8 hours up to 90% capacity
	Back up time on 1 PC load (120W)	15 min
<b>Transfer Time</b>	Minimum line break for transfer to battery	Typical 4-8 msec
<b>Indicators</b>	AC Mode	Green lighting
	Battery Mode	Green flashing
	Fault	Red lighting
<b>Alarms</b>	Battery Mode, Low Battery, Overload, Battery replacement, fault	Audiable alarm is provided
<b>Protection</b>	Full Protection	Overload, discharge, and overcharge protection
<b>Physical</b>	Dimension, D X W X H (mm)	279 X 101 X142
	Net Weight (kgs)	4.2
<b>Environment</b>	Operating Environment	0- 40°C
	Storage Temp	-15°C to 50°C
	Humidity	0-95 % RH @ 0- 40°C (non-condensing)
	Noise Level	Less than 40dB

\* Product specifications are subject to change without further notice  
 \*Battery run time may vary depending upon load.



[Vertiv.com/en-in](http://Vertiv.com/en-in) | E-mail : [marketing.india@vertiv.com](mailto:marketing.india@vertiv.com) | Toll free : 1-800-2096070

**Vertiv Energy Private Limited** | Plot C-20, Rd No.19, Wagle Ind Estate, Thane (W), 400604. India

© 2019 Vertiv Co. All rights reserved. Vertiv, and the Vertiv logo trademarks or registered trademarks of Vertiv Co. All other names and logos referred to are trade names, trademarks or registered trademarks of their respective owners. While every precaution has been taken to ensure accuracy and completeness herein, Vertiv Co. assumes no responsibility, and disclaims all liability, for damages resulting from use of this information or for any errors or omissions. Specifications are subject to change without notice.